

Technical data sheet

Clamp clip, single, FT plastic pressure trough

Item number: 1180282



Suitable for angular steel of 40 mm shaft length.

Clip and bolt made of hot-dip galvanised steel.

Polypropylene pressure trough, halogen-free, colour light grey RAL 7035.



St Steel

FT Hot-dip galvanised

Master data

Item number	1180282
Type	2056W 28 FT
Description 1	Clamp clip
Manufacturer	OBO
Dimension	22-28mm
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	100
Unit of quantity	Piece
Weight	5.95 kg
Weight unit	kg/100 pc.


Technical data sheet

Clamp clip, single, FT plastic pressure trough

Item number: 1180282



Dimensions

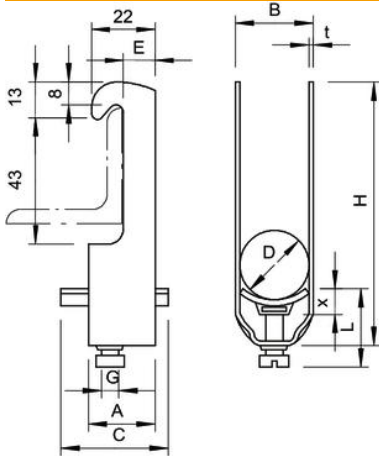

Dimension A	23 mm
Dimension B	33 mm
Dimension C	34 mm
Dimension E	11 mm
Dimension G (mm)	M6
Dimension H	91 mm
Dimension L	27 mm
Dimension t	2 mm
Dimension x	5 mm

Technical data

Number of cables/pipes	1
for 1 cable H	91 mm
for 1 cable L	27
for 2 cable H	121 mm
for 2 cable L	34 mm
for 3 cable H	151 mm
for 3 cable L	47 mm
For pipe diameter, max.	25 mm
For pipe diameter, min.	25 mm
Halogen-free	yes
Max. Tightening torque	3 Nm
With plastic trough	yes
With metal trough	no
Mounting type	Angle profile
Impact-resistant	no
Clamping range D, max.	28 mm
Clamping range D, min.	22 mm
Surface addition	hot galvanised
Material addition	Steel
With counter-trough	no
Material of trough	Plastic
Material quality of trough	Polypropylene