

Technical data sheet

Floor support

Item number: 6288902



Floor support for mounting device installation trunking in front of window facades.
The mesh slats are simply attached to the slat holder.



St Steel

Master data	
Item number	6288902
Type	BOS600
Description 1	Floor support
Manufacturer	OBO
Dimension	600mm
Colour	Pure white; RAL 9010
Material	Steel
Smallest sales unit	1
Unit of quantity	Piece
Weight	150 kg
Weight unit	kg/100 pc.

Technical data sheet



Floor support

Item number: 6288902



Dimensions

Length	580 mm
Width	35 mm
Height	50 mm

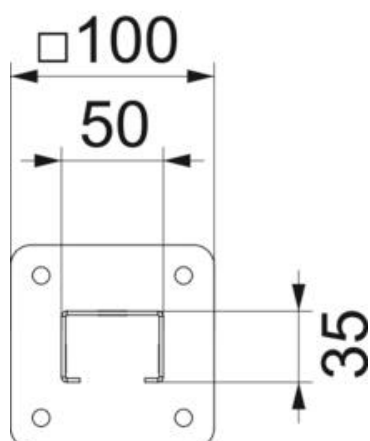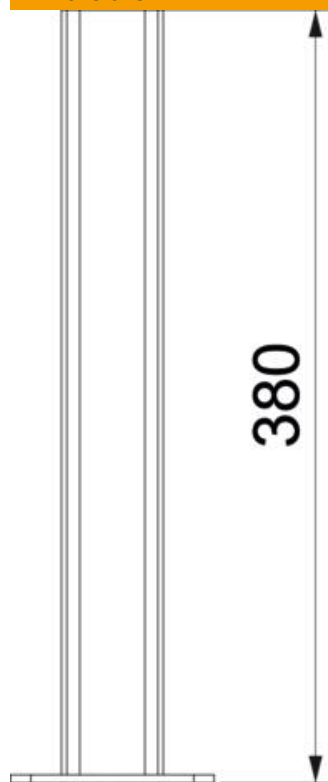

Technical data sheet

Floor support

Item number: 6288902



Technical data

Version for	600–700 mm
Version for	Floor mounting
Fastening type	Screw-on
Trunking mounting	Screw
Protection rating	IP30
Protection rating IK code	IK10
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C