

# Technical data sheet

## Screw-in spacer clip, universal

Item number: 1380222



With M6 thread.  
Universal clip with large tensioning area.

- St** Steel
- G** Electrogalvanized

### Master data

|                                   |                             |
|-----------------------------------|-----------------------------|
| Item number                       | 1380222                     |
| Description 1                     | Distance saddle             |
| Description 2                     | with threaded connection M6 |
| Manufacturer                      | OBO                         |
| Dimension                         | 20-30mm                     |
| Material                          | Steel                       |
| Surface                           | Electrogalvanised           |
| Surface standard                  | EN ISO 19598 / EN ISO 4042  |
| Smallest sales unit               | 50                          |
| Unit of quantity                  | Units                       |
| Weight                            | 3,31 kg                     |
| Weight unit                       | kg/100 pairs                |
| CO Footprint (GWP) Cradle-to-Gate | 0,071 kg COe / 1 Piece      |


# Technical data sheet

## Screw-in spacer clip, universal

Item number: 1380222



### Dimensions

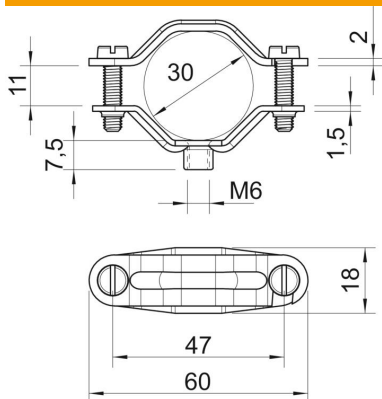

|                   |        |
|-------------------|--------|
| Length            | 60 mm  |
| Width             | 14 mm  |
| Dimension A       | 60 mm  |
| Dimension B       | 47 mm  |
| Dimension b       | 18 mm  |
| Dimension D       | 30 mm  |
| Dimension d min.  | 30 mm  |
| Dimension H       | 7,5 mm |
| Dimension L       | 60 mm  |
| Dimension t1 (mm) | 1,5    |
| Dimension t2 (mm) | 2      |
| Dimension x       | 11 mm  |

### Technical specifications

|                                  |            |
|----------------------------------|------------|
| Version for                      | Closed     |
| Fastening type                   | Screw hole |
| Suitable in fire protection area | no         |
| Halogen-free                     | no         |
| Plastic-covered                  | no         |
| Hole size                        | M6 mm      |
| Material thickness               | 1,5 mm     |
| Bolt                             | M5 x 20    |
| Clamping range D, max.           | 30 mm      |
| Clamping range D, min.           | 20 mm      |
| UV-resistant                     | yes        |