

# Technical data sheet

## Spacer

Item number: 5014018




- For professional laying of round conductors and flat conductors according to DIN VDE 0185-305 (IEC 62305)
- DIN 48833
- Suitable for mounting round conductors Rd 10 or flat conductors FL 30 x 3.5

<b>St</b>	Steel
<b>FT</b>	Hot-dip galvanised

### Master data

Item number	5014018
Type	1811
Description 1	Spacer
Manufacturer	OBO
Dimension	250mm
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	25
Unit of quantity	Units
Weight	19 kg
Weight unit	kg/100 pairs

### Dimensions

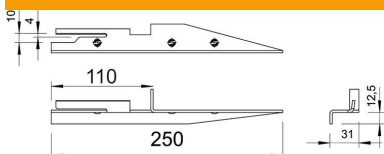

Length	250 mm
Dimension L	250 mm

# Technical data sheet

Spacer

Item number: 5014018



## Technical specifications

Type of accessory	Spacer
Fit	10/FL30 x 3,5 mm