


Technical data sheet

Earthing clip, type 925

Item number: 5040094

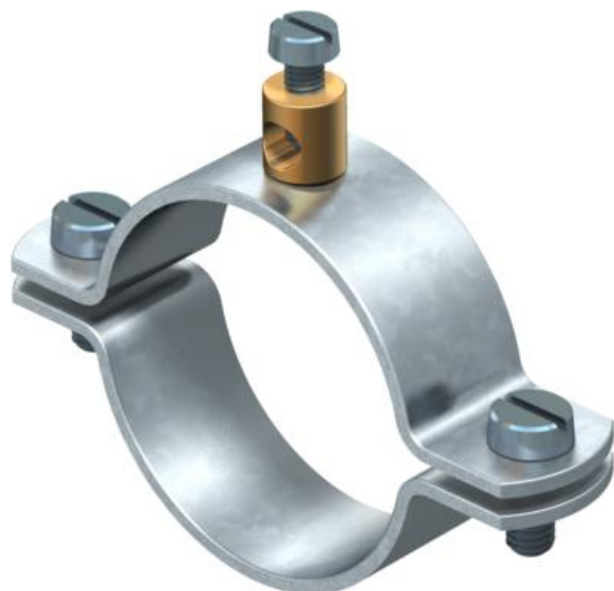

- For pipes 1/4"-1/2" or Ø 11.5-48.3 mm
- Connection options: conductors to 16 mm² with connecting terminal, riveted with brass and 1 cylinder screw M5 x 12
- To 1 1/2" with 2 cylinder screws M6 x 16 (G)

St Steel

G Electrogalvanised

Master data

Item number	5040094
Type	925 3/4
Description 1	Earthing clamp
Description 2	for cables to 16 mm ²
Manufacturer	OBO
Dimension	3/4"
Material	Steel
Surface	Electrogalvanised
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	25
Unit of quantity	Units
Weight	5,316 kg
Weight unit	kg/100 pairs


Technical data sheet

Earthing clip, type 925

Item number: 5040094



Dimensions

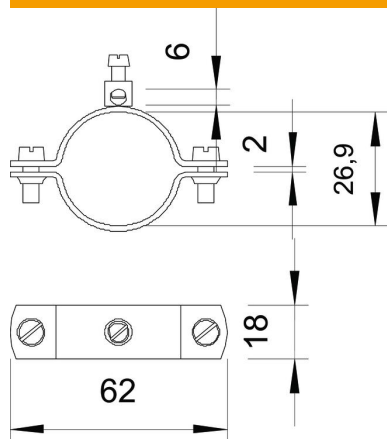

Dimension A	62 mm
Dimension b	18 mm
Dimension D	26,9 mm
Dimension X	2 mm

Technical specifications

Number of conductors	1
Cross-section of cable to be connected, max.	16 mm ²
Cross-section of cable to be connected, min.	0 mm ²
Clamping range D	3/4
Clamping range D, max.	26,9 mm
Clamping range D, min.	24,9 mm