


Technical data sheet

Earthing clip, type 925

Item number: 5040132

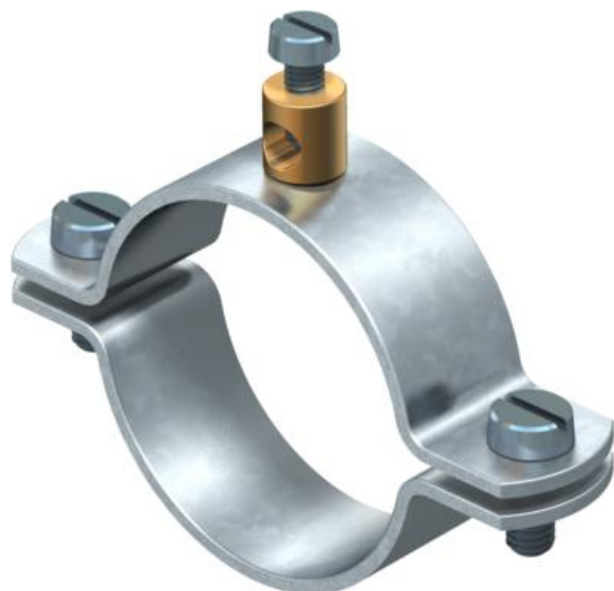

- For pipes 1/4"-1/2" or Ø 11.5-48.3 mm
- Connection options: conductors to 16 mm² with connecting terminal, riveted with brass and 1 cylinder screw M5 x 12
- To 1/2" with 2 cylinder screws M6 x 16 (G)

St Steel

G Electrogalvanised

Master data

Item number	5040132
Type	925 1 1/4
Description 1	Earthing clamp
Description 2	for cables to 16 mm ²
Manufacturer	OBO
Dimension	1 1/4"
Material	Steel
Surface	Electrogalvanised
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	25
Unit of quantity	Units
Weight	7,744 kg
Weight unit	kg/100 pairs


Technical data sheet

Earthing clip, type 925

Item number: 5040132



Dimensions

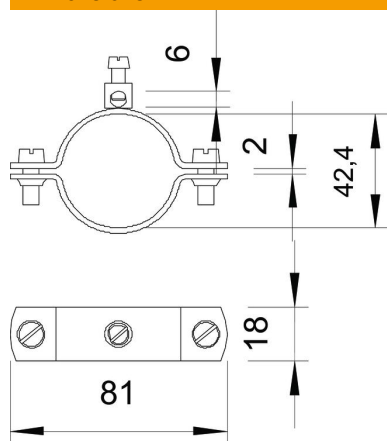

Dimension A	81 mm
Dimension b	18 mm
Dimension D	42,4 mm
Dimension X	2 mm

Technical specifications

Number of conductors	1
Cross-section of cable to be connected, max.	16 mm ²
Cross-section of cable to be connected, min.	0 mm ²
Clamping range D	1 1/4
Clamping range D, max.	42,4 mm
Clamping range D, min.	40,4 mm