

# Technical data sheet

## Earthing strap, type 950

Item number: 5050081



- For pipes  $\varnothing$  1/4"-2"
  - Connection options: conductors to 35 mm<sup>2</sup> or round conductors to  $\varnothing$  6 mm
  - With captive pressure strip, 2 cylinder screws M6 x 16 and 1 hex-head screw M6 x 16
- from galvanised steel, top and bottom part of clip from die-cast zinc

- Zn** Die-cast zinc
- G** Electrogalvanised

### Master data

Item number	5050081
Type	950 Z 3/4
Description 1	Earthing clamp
Description 2	for round cable
Manufacturer	OBO
Dimension	3/4"
Material	Die-cast zinc
Surface	Electrogalvanised
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	10
Unit of quantity	Units
Weight	7,62 kg
Weight unit	kg/100 pairs


# Technical data sheet

## Earthing strap, type 950

Item number: 5050081



### Dimensions

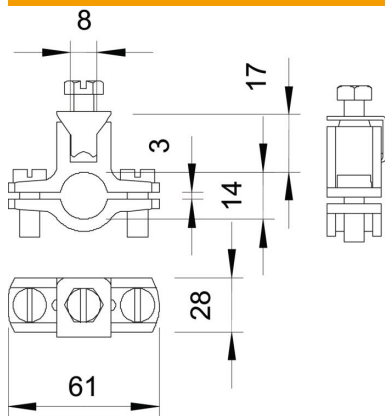

Dimension A	61 mm
Dimension D	28 mm
Dimension X	3 mm

### Technical specifications

Number of conductors	1
Cross-section of cable to be connected, max.	35 mm <sup>2</sup>
Cross-section of cable to be connected, min.	0 mm <sup>2</sup>
Clamping range D	3/4
Clamping range D, max.	28 mm
Clamping range D, min.	25 mm