

Technical data sheet

Earthing strap, type 950

Item number: 5050138



- For pipes \varnothing 1/4"-2"
 - Connection options: conductors to 35 mm² or round conductors to \varnothing 6 mm
 - With captive pressure strip, 2 cylinder screws M6 x 16 and 1 hex-head screw M6 x 16
- from galvanised steel, top and bottom part of clip from die-cast zinc

- Zn** Die-cast zinc
- G** Electrogalvanised

Master data

Item number	5050138
Type	950 Z 1 1/4
Description 1	Earthing clamp
Description 2	for round cable
Manufacturer	OBO
Dimension	1 1/4"
Material	Die-cast zinc
Surface	Electrogalvanised
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	10
Unit of quantity	Units
Weight	10,03 kg
Weight unit	kg/100 pairs


Technical data sheet

Earthing strap, type 950

Item number: 5050138



Dimensions

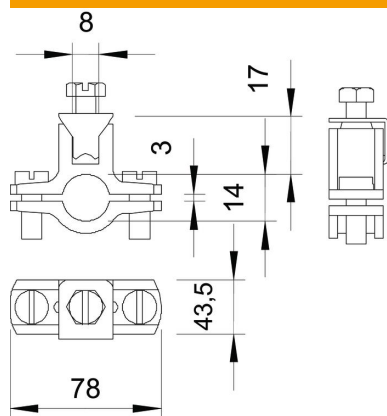

Dimension A	78 mm
Dimension D	43,5 mm
Dimension X	3 mm

Technical specifications

Number of conductors	1
Cross-section of cable to be connected, max.	35 mm ²
Cross-section of cable to be connected, min.	0 mm ²
Clamping range D	1 1/4
Clamping range D, max.	43,5 mm
Clamping range D, min.	40,5 mm