

# Technical data sheet

## Connection and end piece

Item number: 5304997



5011: End piece


- For attaching to steel structures or bolting to earthing fixed points
- For attachments: Round conductor Rd 8-10 and flat conductor FL30 x 3.5
- 2x attaching hole  $\varnothing$  11 mm
- 1x attaching hole  $\varnothing$  D mm

<b>St</b>	Steel
<b>FT</b>	Hot-dip galvanised

### Master data

Item number	5304997
Type	5011
Description 1	Connection terminal
Manufacturer	OBO
Dimension	80x25x25
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	10
Unit of quantity	Units
Weight	7,064 kg
Weight unit	kg/100 pairs

### Dimensions

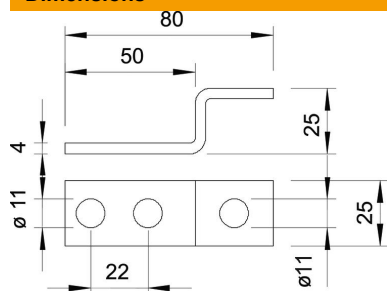

Dimension d min.	11 mm
------------------	-------

### Technical specifications

Type of fastening screw	Miscellaneous
Type of connector	End piece
Suitable for connection	Round conductor Rd 8-10 / flat conductor FI 30
Intermediate plate	no